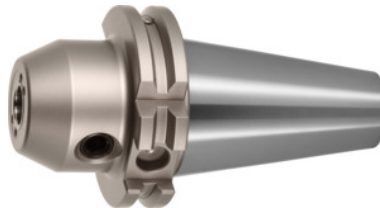


Garant
Side lock arbor Form ADB with cooling channel bores, nickel-plated, SK 40 short, Clamping \varnothing D1: 20mm

Order data

Order number	300120 20
GTIN	4045197945723
Item class	31A

Description
Version:
GARANT –

All shanks hard turned (for smooth cutting action!). Balancing quality G 2.5 / G 25,000 rpm

With coolant supply holes that can be plugged.

Special nickel plating.

With Balluff/RFID chip bore.

Application:

For clamping tools with side flats to DIN 1835 B and DIN 6535 HB.

Optional extras:

Pull studs (PS) No. 308600 – 308806. Pull stud wrenches No. 308820; 308835.

Technical description

Spare clamping screw No. 30 9900	20
External \varnothing D	52 mm
Clamping \varnothing D ₁	20 mm
Overhang dimension A	63 mm
Adapter	SK 40 short
Standard	DIN 6359

Arbor standard	ISO 7388-1
Shape	ADB
Cooling channel bore	lockable
Balance quality G at rotational speed	G 2.5 at 25,000 rpm
Concentricity	≤ 3 μm
Machining strategy	HPC
Type of product	Side lock arbor

Accessories

Spare clamping screw for chucks with clamping Ø D1 20 mm	309900 20
--	-----------