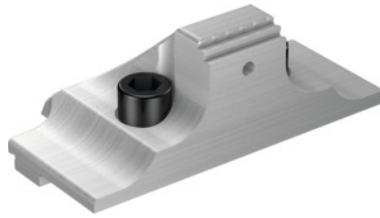


Garant**Top jaw Gripp, single piece, for type: 125/32****Order data**

Order number	361123 125/32
GTIN	4045197953506
Item class	310

Description**Version:**

Clamping step with a height of 5 mm and 3 mm contact area.

Application:

Ideal for rough machining.

Suitable for:

5-axis vice set No. 361100 and clamping module No. 361105 – 361110.

Supplied with:

Fastening screws.

Note:

Type GS with gripp step and smooth clamping step

Technical description

Jaw length l	68.5 mm
Height h ₁	3 mm
Height h ₂	3 mm
Jaw width b	125 mm
Jaw height h	45 mm
suitable for colour code	Xpent1-2
Length l ₁	3 mm

Length l ₂	3 mm
Type of product	Vice jaws