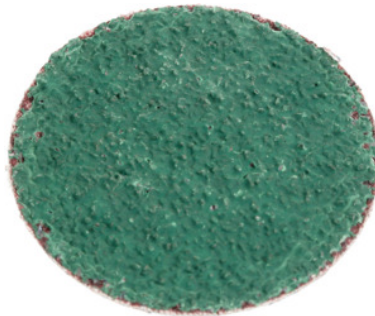


**Grinding disc (ZA), Ø 50.8 mm, Grit: 50****Order data**

| | |
|--------------|---------------|
| Order number | 554018 50 |
| GTIN | 4045197966124 |
| Item class | 52E |

Description**Version:**

Zirconium aluminium oxide (ZA) with the **best cost-benefit ratio** for economic performance on steel and non-ferrous metals.

Technical description

| | |
|------------------------|-------------------------|
| Disc Ø | 50.8 mm |
| Grit | 50 |
| Grinding medium code | ZA |
| Product name attribute | Ø 50.8 mm |
| maximum speed | 25000 min ⁻¹ |
| Type of product | Grinding wheel |

User data

| | Suitability | V _c | ISO code |
|--|-------------|----------------|----------|
|--|-------------|----------------|----------|

| | |
|--------------------------------|---|
| Steel < 900 N/mm ² | suitable |
| Steel < 1400 N/mm ² | suitable |
| Steel < 55 HRC | suitable |
| Steel < 60 HRC | suitable |
| Steel < 67 HRC | suitable only under restricted conditions |
| INOX | suitable only under restricted conditions |
| Ti | suitable only under restricted conditions |
| GG(G) | suitable |
| CuZn | suitable only under restricted conditions |
| dry | suitable |