


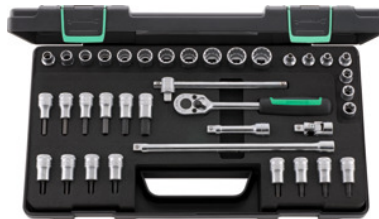

## Socket set 3/8 inch square drive 37 pieces, Type: 12



### Order data

Order number	634811 12
GTIN	4018754260461
Item class	63A

### Description

#### Version:

**Drives / accessories to DIN 3122 / 3123; sockets to DIN 3124.** Internal / external square drives to **DIN 3120**.

#### Application:

For hexagon head screws / nuts with thread M5 – M12, for external Torx® with thread M4 – M12, for socket head screws with thread M5 – M12, for internal Torx® with thread M3 – M8.

#### Material:

Chrome alloy steel, chrome-plated.

#### Supplied with:

Bi-hexagon sockets: 11 pcs. No. 637000

size 8; 10; 11; 12; 13; 14; 15; 16; 17; 18; 19

Sockets, for Torx®: 7 pcs. No. 637450

size E5; E6; E7; E8; E10; E12; E14

Screwdriver sockets, hexagon: 6 pcs. No. 637600 size 4; 5; 6; 7; 8; 10

Screwdriver sockets for Torx®: 8 pcs. No. 637560

size TX9; TX10; TX15; TX20; TX25; TX27; TX30; TX40

T-handle: 1 pc. No. 635700

Extensions: 2 pcs. No. 635400 size 75; 240

Universal joint: 1 pc. No. 636200

Ratchet: 1 pc. No. 635000

Presented in: ABS plastic box

#### Note:

**PLEASE NOTE!**

An alternative from GARANT is also available for this product.

Recommended product number: 634799

## Technical description

Drive profile	Bi-hex socket
Drive profile	Socket for TORX® screws
Drive profile	Hexagon screwdriver
Drive profile	Screwdriver for TORX® screws
Width across flats range, hexagon wrenches	4-10 mm
Width across flats range, bi-hex sockets	8-19 mm
Square drive	3/8 in
Number of pieces	37
Packaging	ABS plastic box
Length	413 mm
Width	230 mm
Height	57 mm
Type of product	Socket spanner

## Accessories

Socket, 3/8 inch for Torx® Torx® profile E7	637450 E7
Bi-hexagon socket, 3/8 inch Width across flats 19 mm	637000 19
Hexagon bit socket, 3/8 inch Hexagon 5 mm	637600 5
Bi-hexagon socket, 3/8 inch Width across flats 11 mm	637000 11
Bi-hexagon socket, 3/8 inch Width across flats 13 mm	637000 13
Socket, 3/8 inch for Torx® Torx® profile E5	637450 E5
Bit socket, for Torx®, 3/8 inchshort Torx® profile TX9	637560 TX9
Bit socket, for Torx®, 3/8 inchshort Torx® profile TX27	637560 TX27
Bi-hexagon socket, 3/8 inch Width across flats 15 mm	637000 15
Bi-hexagon socket, 3/8 inch Width across flats 12 mm	637000 12

Bit socket, for Torx®, 3/8 inchshort Torx® profile TX20	637560 TX20
Bit socket, for Torx®, 3/8 inchshort Torx® profile TX25	637560 TX25
Socket, 3/8 inch for Torx® Torx® profile E6	637450 E6
Bi-hexagon socket, 3/8 inch Width across flats 18 mm	637000 18
Bi-hexagon socket, 3/8 inch Width across flats 16 mm	637000 16
Socket, 3/8 inch for Torx® Torx® profile E10	637450 E10
Hexagon bit socket, 3/8 inch Hexagon 7 mm	637600 7
Bi-hexagon socket, 3/8 inch Width across flats 8 mm	637000 8
Bi-hexagon socket, 3/8 inch Width across flats 17 mm	637000 17
Bi-hexagon socket, 3/8 inch Width across flats 10 mm	637000 10
Extension, 3/8 inch overall length 75 mm	635400 75
Hexagon bit socket, 3/8 inch Hexagon 8 mm	637600 8
Bit socket, for Torx®, 3/8 inchshort Torx® profile TX10	637560 TX10
Bit socket, for Torx®, 3/8 inchshort Torx® profile TX15	637560 TX15
Bi-hexagon socket, 3/8 inch Width across flats 14 mm	637000 14
Hexagon bit socket, 3/8 inch Hexagon 4 mm	637600 4
Bit socket, for Torx®, 3/8 inchshort Torx® profile TX30	637560 TX30
Socket, 3/8 inch for Torx® Torx® profile E12	637450 E12
T-handle, 3/8 inch overall length 165 mm	635700 165
Socket, 3/8 inch for Torx® Torx® profile E14	637450 E14
Universal joint, 3/8 inch Type 3/8	636200 3/8
Extension, 3/8 inch overall length 240 mm	635400 240
Socket, 3/8 inch for Torx® Torx® profile E8	637450 E8
Bit socket, for Torx®, 3/8 inchshort Torx® profile TX40	637560 TX40
Hexagon bit socket, 3/8 inch Hexagon 6 mm	637600 6
Hexagon bit socket, 3/8 inch Hexagon 10 mm	637600 10