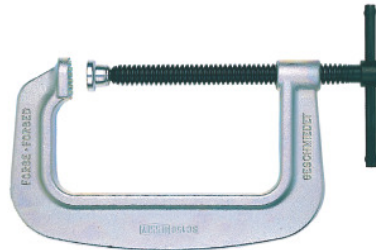


**C-clamp, Jaw capacity: 100mm****Order data**

Order number	861550 100
GTIN	4008158019208
Item class	83K

**Description****Version:**

C-shape, forged steel, tempered. Strong spindle with trapezoidal thread and movable special jaw anvil.

**Application:**

**Maximum clamping pressure up to 22,000 N.**

**Technical description**

Spindle thickness	16 mm
Jaw capacity	100 mm
Throat	75 mm
Type of product	Clamp