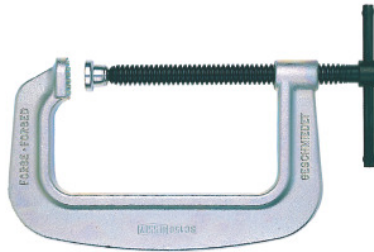


**C-clamp, Jaw capacity: 120mm****Order data**

Order number	861550 120
GTIN	4008158019215
Item class	83K

Description**Version:**

C-shape, forged steel, tempered. Strong spindle with trapezoidal thread and movable special jaw anvil.

Application:

Maximum clamping pressure up to 22,000 N.

Technical description

Throat	85 mm
Jaw capacity	120 mm
Spindle thickness	18 mm
Type of product	Clamp