


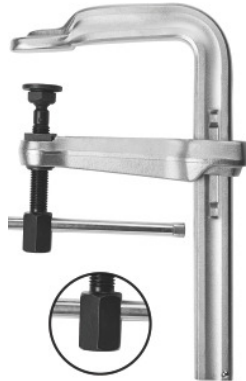

Extra-heavy all-steel high-performance clamp with special jaw anvil, Jaw capacity: 300mm



Order data

Order number	861400 300
GTIN	4008158007700
Item class	83K

Description

Version:

Beam and fixed jaw made of bright steel section (special profile), tempered and electro-galvanised. Slide jaw made of steel, drop-forged, tempered, and electro-galvanised. Wear-resistant smooth-running steel spindle with metric thread. Long working life due to heat-resistant special pressure pad with sintered steel inlay, can tilt through 35°. Spindle tempered and burnished with adjustable clamp handle.

Application:

For heaviest duty clamping of workpieces in steel construction, blacksmith's shops, HGV bodywork, machine tool manufacture etc. The movable special jaw anvil permits clamping diagonal workpieces up to 35°. **Maximum clamping pressure up to approx. 35000 N.**

Technical description

Cross section of the slide rail	50×25 mm
Jaw capacity	300 mm
Weight	10.5 kg

Throat	200 mm
Type of product	Clamp

Accessories

Threaded socket with circlip	861450
Spindle with tightening bar and pressure plate	861440
Pressure plate including fastenings	861430