


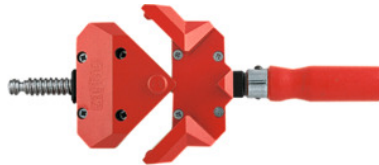

## Angle clamp, light version, maximum aperture: 60mm



### Order data

Order number	862700 60
GTIN	4008158010410
Item class	83K

### Description

#### Version:

Metal body with plastic coating, clamping angle 90°. Clamping jaws movable, allowing **different thicknesses of material** to be clamped.

#### Application:

For clamping flat material, profiles etc. at the correct angle for bolting, gluing together etc. Not for use as a welding clamp. Quick adjustment feature.

### Technical description

maximum aperture	60 mm
Clamping range for 2 non-identical components	25 / 140 mm
Clamping range for 2 identical components	100 / 100 mm
Jaw height	36 mm
Type of product	Welder's angle clamps