


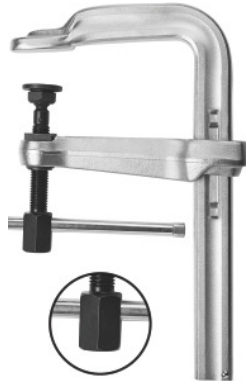

Extra-heavy all-steel high-performance clamp with special jaw anvil, Jaw capacity: 1000mm



Order data

Order number	861400 1000
GTIN	4008158007670
Item class	83K

Description

Version:

Beam and fixed jaw made of bright steel section (special profile), tempered and electro-galvanised. Slide jaw made of steel, drop-forged, tempered, and electro-galvanised. Wear-resistant smooth-running steel spindle with metric thread. Long working life due to heat-resistant special pressure pad with sintered steel inlay, can tilt through 35°. Spindle tempered and burnished with adjustable clamp handle.

Application:

For heaviest duty clamping of workpieces in steel construction, blacksmith's shops, HGV bodywork, machine tool manufacture etc. The movable special jaw anvil permits clamping diagonal workpieces up to 35°. **Maximum clamping pressure up to approx. 35000 N.**

Technical description

Throat	200 mm
Cross section of the slide rail	50×25 mm
Weight	17.3 kg

Jaw capacity	1000 mm
Type of product	Clamp

Accessories

Pressure plate including fastenings	861430
Spindle with tightening bar and pressure plate	861440
Threaded socket with circlip	861450