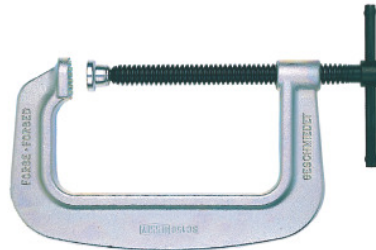


**C-clamp, Jaw capacity: 60mm****Order data**

Order number	861550 60
GTIN	4008158019185
Item class	83K

Description**Version:**

C-shape, forged steel, tempered. Strong spindle with trapezoidal thread and movable special jaw anvil.

Application:

Maximum clamping pressure up to 22,000 N.

Technical description

Jaw capacity	60 mm
Throat	55 mm
Spindle thickness	12 mm
Type of product	Clamp