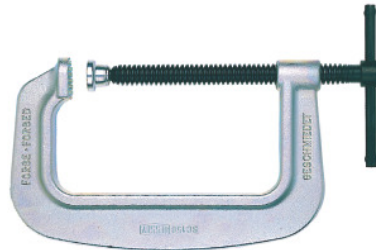


**C-clamp, Jaw capacity: 80mm****Order data**

Order number	861550 80
GTIN	4008158019192
Item class	83K

**Description****Version:**

C-shape, forged steel, tempered. Strong spindle with trapezoidal thread and movable special jaw anvil.

**Application:**

**Maximum clamping pressure up to 22,000 N.**

**Technical description**

Throat	65 mm
Spindle thickness	14 mm
Jaw capacity	80 mm
Type of product	Clamp