


Cantilever arm rack, double-sided, Depth 2×600 mm, Rack width: 5000mm

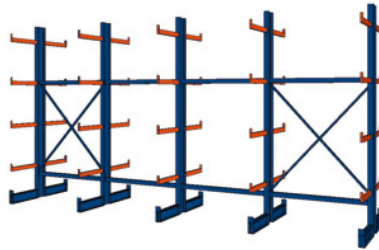

Order data

| | |
|--------------|---------------|
| Order number | 991718 5000 |
| GTIN | 2050001760692 |
| Item class | 960 |

Description

Version:

Stiles IPE profiles IPE 120 hot-rolled. IPE profile cantilever arms, bolted. Welded-on anti-roll restraints. Cantilever arms to take plug-in anti-roll restraints are available on request.

Description:

Dimensions:

Number of bays × axial spacing + 1 stile width (64 mm).

Overall depth = Nominal depth + 120 mm for stiles or stiles base (applies to single-sided and double-sided racking).

Supplied with:

All racks include horizontal ties and cross braces, together with heavy-duty anchors for floor anchoring.

Colour:

Stiles RAL 5010 gentian blue, cantilever arms RAL 2004 pure orange.

Note:

- **Further dimensions available as standard sizes: Heights 2000 / 3000 / 3500 mm. Depth 750 mm. Widths 750 / 1000 mm.**
- **Cantilever arm racking with non-standard sizes and load capacities available on request.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

Technical description

| | |
|------------|---------|
| Rack width | 5000 mm |
|------------|---------|

| | |
|---|---------------------------|
| Axial spacing = Bay width | 1250 mm |
| Number of levels | 10 |
| Number of cantilever arms double-sided | 40 |
| Assembled size | 5064 mm |
| Number of rack bays | 4 |
| Number of rack stiles | 5 |
| Rack height | 2500 mm |
| Cantilever arm load capacity | 400 kg |
| Cantilever arm racking height | 2500 mm |
| Height adjustment interval | 100 mm |
| Type of installation | bolted-on cantilever arms |
| Cantilever arm depth | 400-600 mm |
| Colour selection | RAL 5010, 2004 |
| Product name attribute | Depth 2×600 mm |
| Depth double-ended | 600 mm |
| Load capacity per cantilever arm | 400 kg |
| Load capacity per stile including floor-level storage | 4000 kg |
| Type of product | Cantilever arm rack |