


Cantilever arm rack, single-sided, Depth 500 mm, Rack width: 6250mm

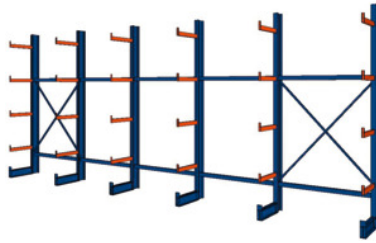

Order data

Order number	991712 6250
GTIN	2050001760500
Item class	960

Description

Version:

Stiles IPE profiles IPE 120 hot-rolled. IPE profile cantilever arms, bolted. Welded-on anti-roll restraints. Cantilever arms to take plug-in anti-roll restraints are available on request.

Description:

Dimensions:

Number of bays × axial spacing + 1 stile width (64 mm).

Overall depth = Nominal depth + 120 mm for stiles or stiles base (applies to single-sided and double-sided racking).

Supplied with:

All racks include horizontal ties and cross braces, together with heavy-duty anchors for floor anchoring.

Colour:

Stiles RAL 5010 gentian blue, cantilever arms RAL 2004 pure orange.

Note:

- **Further dimensions available as standard sizes: Heights 2000 / 3000 / 3500 mm. Depth 750 mm. Widths 750 / 1000 mm.**
- **Cantilever arm racking with non-standard sizes and load capacities available on request.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

Technical description

Axial spacing = Bay width	1250 mm
---------------------------	---------

Number of rack stiles	6
Number of rack bays	5
Assembled size	6314 mm
Number of levels	5
Rack width	6250 mm
Number of cantilever arms single-sided	24
Rack height	2500 mm
Cantilever arm load capacity	400 kg
Cantilever arm racking height	2500 mm
Height adjustment interval	100 mm
Type of installation	bolted-on cantilever arms
Cantilever arm depth	400-600 mm
Colour selection	RAL 5010, 2004
Product name attribute	Depth 500 mm
Depth single-ended	500 mm
Load capacity per cantilever arm	400 kg
Load capacity per stile including floor-level storage	2000 kg
Type of product	Cantilever arm rack