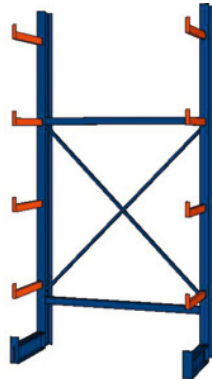


**Cantilever arm rack, single-sided, Depth 600 mm, Rack width: 1250mm****Order data**

Order number	991713 1250
GTIN	2050001760517
Item class	97K

**Description****Version:**

Stiles IPE profiles IPE 120 hot-rolled. IPE profile cantilever arms, bolted. Welded-on anti-roll restraints. Cantilever arms to take plug-in anti-roll restraints are available on request.

**Description:****Dimensions:**

Number of bays  $\times$  axial spacing + 1 stile width (64 mm).

Overall depth = Nominal depth + 120 mm for stiles or stiles base (applies to single-sided and double-sided racking).

**Supplied with:**

All racks include horizontal ties and cross braces, together with heavy-duty anchors for floor anchoring. **Single-sided rack (basic rack):** 2 single-sided stiles each with 1 floor-level storage and 4 cantilever arms (= 5 storage levels).

**Colour:**

Stiles RAL 5010 gentian blue, cantilever arms RAL 2004 pure orange.

**Note:**

- **Further dimensions available as standard sizes: Heights 2000 / 3000 / 3500 mm. Depth 750 mm. Widths 750 / 1000 mm.**
- **Cantilever arm racking with non-standard sizes and load capacities available on request.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

## Technical description

Number of rack stiles	2
Rack height	2500 mm
Rack width	1250 mm
Number of levels	5
Assembled size	1314 mm
Number of rack bays	1
Number of cantilever arms single-sided	8
Axial spacing = Bay width	1250 mm
Cantilever arm load capacity	400 kg
Cantilever arm racking height	2500 mm
Height adjustment interval	100 mm
Type of installation	bolted-on cantilever arms
Cantilever arm depth	400-600 mm
Colour selection	RAL 5010, 2004
Product name attribute	Depth 600 mm
Depth single-ended	600 mm
Load capacity per cantilever arm	400 kg
Load capacity per stile including floor-level storage	2000 kg
Type of product	Cantilever arm rack