


## Cantilever arm rack, single-sided, Depth 400 mm, Rack width: 6250mm

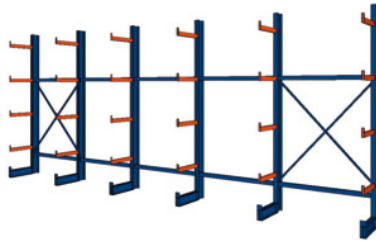

### Order data

|              |               |
|--------------|---------------|
| Order number | 991711 6250   |
| GTIN         | 2050001760456 |
| Item class   | 960           |

### Description

#### Version:

Stiles IPE profiles IPE 120 hot-rolled. IPE profile cantilever arms, bolted. Welded-on anti-roll restraints. Cantilever arms to take plug-in anti-roll restraints are available on request.

#### Description:

#### Extension size:

Number of bays  $\times$  axial spacing + 1 stile width (64 mm).

Overall depth = Nominal depth + 120 mm for stiles or stiles base (applies to single-sided and double-sided racking).

#### Supplied with:

All racks include horizontal ties and cross braces, together with heavy-duty anchors for floor anchoring.

#### Colour:

Stiles RAL 5010 gentian blue, cantilever arms RAL 2004 pure orange.

#### Note:

- **Further dimensions available as standard sizes: Heights 2000 / 3000 / 3500 mm. Depth 750 mm. Widths 750 / 1000 mm.**
- **Cantilever arm racking with non-standard sizes and load capacities available on request.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

### Technical description

|  |    |
|--|----|
| Number of cantilever arms single-sided | 24 |
|--|----|

|   |                           |
|---|---------------------------|
| Number of rack stiles                                 | 6                         |
| Axial spacing = Bay width                             | 1250 mm                   |
| Number of levels                                      | 5                         |
| Rack width  | 6250 mm                   |
| Assembled size  | 6314 mm                   |
| Rack height   | 2500 mm                   |
| Number of rack bays                                   | 5                         |
| Cantilever arm load capacity                          | 400 kg                    |
| Cantilever arm racking height                         | 2500 mm                   |
| Height adjustment interval                            | 100 mm                    |
| Type of installation                                  | bolted-on cantilever arms |
| Cantilever arm depth                                  | 400-600 mm                |
| Colour selection                                      | RAL 5010, 2004            |
| Product name attribute                                | Depth 400 mm              |
| Depth single-ended                                    | 400 mm                    |
| Load capacity per cantilever arm                      | 400 kg                    |
| Load capacity per stile including floor-level storage | 2000 kg                   |
| Type of product                                       | Cantilever arm rack       |