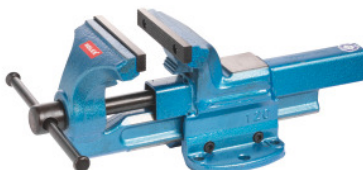


**Bench vice with interchangeable jaws, Jaw width: 160mm****Order data**

Order number	967430 160
GTIN	4045197694416
Item class	92H

Description**Version:**

Entirely of steel – guaranteed unbreakable.

Slides forward on opening. With forged pipe clamping jaws underneath the normal jaws.

Lead screw with trapezoidal thread, enclosed and protected against dirt.

Double Vee form guide with adjustment facility.

With anvil shoulder for light shaping and upsetting.

With serrated, hardened jaws (exchangeable).

Supplied with:

Fasteners for attachment to the workbench.

Note:

For suitable height adjuster see No. 967540.

Technical description

Material	Drop forged steel
Weight	27 kg
Jaw capacity	210 mm
Clamping depth	100 mm
Opening direction	opens to the front
Pipe jaws clamp pipes with outer Ø	25 - 100 mm
Jaw width	160 mm

exchangeable jaws	yes
Type of product	Machinist's vice

Accessories

Pair of spare jaws with screws for No. 967430 Jaw width 160 mm	967440 160
Pair of magnetic vice jaws Aluminium, profiled Jaw width 160 mm	967722 160
Pair of magnetic vice jaws Aluminium / fibre cover, smooth Jaw width 160 mm	967724 160
Bench vice mounting plate	967330
Bench vice mounting plate, bamboo Size 300X250	967328 300X250
Pair of light metal vice jaws with spring clips Jaw width 160 mm	967711 160
Pair of magnetic vice jaws Aluminium, Vee form Jaw width 160 mm	967723 160
Height adjuster for vices No. 967350 / 7360 / 7420 / 7430 suitable for vice size 160/180	967540 160/180