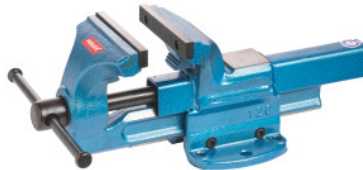


**Bench vice with interchangeable jaws, Jaw width: 120mm****Order data**

Order number	967430 120
GTIN	4045197694393
Item class	92H

**Description****Version:**

**Entirely of steel – guaranteed unbreakable.**

**Slides forward on opening.** With forged pipe clamping jaws underneath the normal jaws.

Lead screw with trapezoidal thread, enclosed and protected against dirt.

Double Vee form guide with adjustment facility.

With anvil shoulder for light shaping and upsetting.

With serrated, hardened jaws (exchangeable).

**Supplied with:**

Fasteners for attachment to the workbench.

**Note:**

For suitable height adjuster see No. 967540.

**Technical description**

Opening direction	opens to the front
Material	Drop forged steel
Weight	9 kg
Clamping depth	65 mm
Jaw capacity	120 mm
Pipe jaws clamp pipes with outer Ø	20 - 55 mm
Jaw width	120 mm

exchangeable jaws	yes
Type of product	Machinist's vice

---

## Accessories

Bench vice mounting plate	967330
Pair of spare jaws with screws for No. 967430 Jaw width 120 mm	967440 120
Pair of magnetic vice jaws Aluminium, Vee form Jaw width 120 mm	967723 120
Pair of light metal vice jaws with spring clips Jaw width 120 mm	967711 120
Pair of magnetic vice jaws Aluminium / fibre cover, smooth Jaw width 120 mm	967724 120
Height adjuster for vices No. 967350 / 7360 / 7420 / 7430 suitable for vice size 120	967540 120
Bench vice mounting plate, bamboo Size 300X250	967328 300X250
Pair of magnetic vice jaws Aluminium, profiled Jaw width 120 mm	967722 120