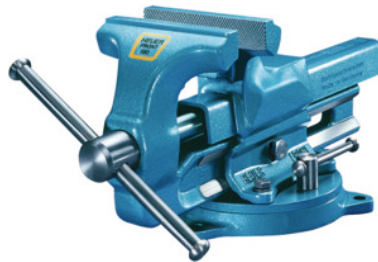


BROCKHAUS | HEUER

“Heuer-Front” bench vice with swivel base, Jaw width: 100mm**Order data**

Order number	967370 100
GTIN	2050002047716
Item class	93Q

Description**Version:****Made entirely of forged steel – guaranteed unbreakable.****Opens forward.** With forged pipe jaws underneath the normal jaws. Strong spindle with **two-start trapezoidal thread** for quick opening and closing of the jaws. Galvanised spindle wrench with riveted steel circlips. Spindle and guide tracks protected from dirt. Adjustable, double-sided Vee guide.

With reinforced anvil shoulder for shaping and compressing work.

Serrated surface-hardened jaws, not interchangeable.

Swivel base can be rotated continuously 360° and can be securely locked in any position.

Supplied with:

Fastening screws for attachment to the worktop.

Colour:Hammer-effect blue, **powder-coated.****Technical description**

Material	Drop forged steel
Opening direction	opens to the front
Jaw width	100 mm
Series	Heuer Front

exchangeable jaws	no
Type of product	Machinist's vice

Accessories

Pair of magnetic vice jawsAluminium / fibre cover, smooth Jaw width 100 mm	967724 100
Pair of magnetic vice jawspolyurethane, Vee form Jaw width 100 mm	967729 100
Pair of magnetic vice jawspolyurethane, serrated Jaw width 100 mm	967728 100
Pair of magnetic vice jawsFelt, smooth Jaw width 100 mm	967726 100
Bench vice mounting plate, bamboo Size 300X250	967328 300X250
Bench vice mounting plate	967330
Pair of magnetic vice jawsAluminium, Vee form Jaw width 100 mm	967723 100
Pair of magnetic vice jawsAluminium, profiled Jaw width 100 mm	967722 100
Pair of light metal vice jaws with spring clips Jaw width 100 mm	967711 100
Pair of magnetic vice jawsAluminium, smooth, standard Jaw width 100 mm	967721 100
Pair of magnetic vice jawsRubber, smooth Jaw width 100 mm	967727 100