


## Workplace mat Ease Width 122 cm, grey, Length: 200cm

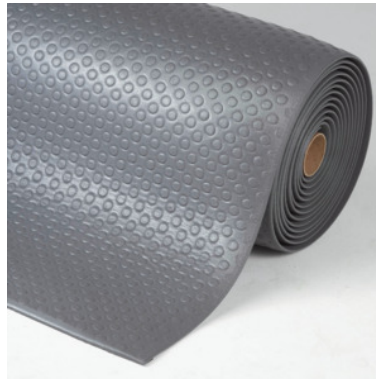

### Order data

Order number	964511 200
GTIN	2050001943439
Item class	96C

### Description

#### Version:

Industrial workplace mats **for medium heavy duty:**

- **Of grey micro-cell vinyl with raised surface. Hard-wearing protective Dyna Shield™ surface (for a longer working life).**
- **Bevelled edges on all sides to eliminate the risk of tripping when walking on to the mat.**
- **Sealed all round to prevent penetration of moisture.**
- **Combustibility class 2 to NFPA safety code 101.**
- **Mat thickness 12.7 mm, weight approx. 4 kg/m<sup>2</sup>.**
- **Non-slip characteristics tested to DIN 51130 and BGR 181.**

#### Note:

Micro-cell vinyl is **not** resistant to industrial greases, cooling lubricants etc. Suitable for use in dry areas.

### Technical description

Bevelling	4-sided
plug-in	no
Thickness	12.7 mm

silicone-free	yes
Surface	Raised surface
Length	200 cm
with safety edges	without
Material	Microcell vinyl
Weight per unit area	4 kg/m <sup>2</sup>
Standing in comfort	Insulation (temperature)
Standing in comfort	Anti-slip
Standing in comfort	Anti-fatiguing
Shock protection	Floor
Material characteristics	not oil-resistant
Colour	grey
Type of product	Workplace mat