


## Workplace mat, angle Length 91 cm, black, Angle: 22,5°

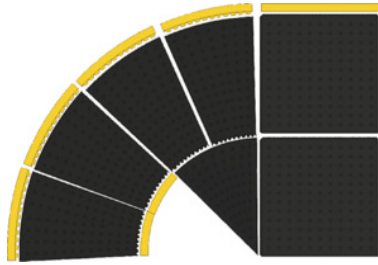

### Order data

Order number	964556 22,5
GTIN	662641861268
Item class	96C

### Description

#### Version:

- **Industrial workplace mat with sealed non-slip surface.**
- **13 mm thick material offers high ergonomic benefits and anti-fatiguing effect.**
- **Flexible interlocking system tiles 91×91 cm, internal angle (45°) and external angle (22.5°) permit optimum adaptability to the locality.**
- **Flexible edging allows creation of internal and external corners.**
- **Non-slip characteristics R9 to DIN 51130 and BGR 181. 100 % natural rubber mixture for general-purpose use.**
- **Free of heavy metals and silicones, therefore suitable for paint shops.**
- **Free of DOP, DMF and substances destructive of the ozone layer.**

45° internal angle tile 4.5 kg, colour black. 22.5° internal angle tile 6.4 kg, colour black.

#### Suitable for:

Edge strips No. 964558 size 22.5IN and 22.5OUT are suitable for workplace mat No. 964556 size 22.5.

### Technical description

with safety edges	can be extended
plug-in	yes
Thickness	13 mm
Angle	22,5 degrees

Surface	Anti-slip surface
Material	Natural rubber mixture
Length	91 cm
Weight	6.4 kg
Internal angle	22.5 degrees
Non-slip characteristics to DIN 51130, BGR 181	R9
Manufacturer's designation	Skywalker HD O-Curve (black)
Standing in comfort	Insulation (temperature)
Standing in comfort	Anti-slip
Standing in comfort	Anti-fatiguing
Shock protection	Floor
Material characteristics	not oil-resistant
Colour	black
Type of product	Workplace mat