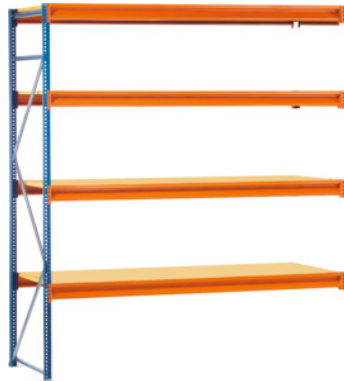


**Wide-span add-on rack, Depth 800 mm, Height / Shelf width: 3000/1785mm****Order data**

Order number	990995 3000/1785
GTIN	4004514225603
Item class	960

**Description****Version:**

Framework galvanised. Optionally galvanised 25 mm steel panels or chipboard. Different types of cross beam depending on the required load per shelf (cross piece height 55 – 85 mm). Quick assembly by simply plugging in the type ZG cross beams. **Shelf loading** maximum 1050 kg, **bay loading** maximum 3500 kg.

**Description:****Assembled size:**

Nominal length + number of stiles × 57 mm.

**Application:**

Storage of bulky, awkward, and heavy goods. Deposit and retrieval available from both sides.

**Colour:**

Stiles similar RAL 5017 Traffic blue, cross beams similar to RAL 2004 Pure orange **powder-coated**.

**Note:**

- **The free unsupported length (K) must not be more than 1200 mm, but only for a bay load of max. 2600 kg. The permissible bay load must be reduced in recognition of this shelf.**
- **Floor and wall fastenings are not included.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

**Technical description**

Shelf load capacity	670 kg
Assembled size add-on rack width	1842 mm
Height	3000 mm
Storage shelf depth	800 mm
Shelf width	1785 mm
Rack installation	Extension rack
Customer assembly	yes
Material of storage level	Chipboard shelf
Width	1842 mm
Number of storage levels chipboard shelf	5
Depth	800 mm
Rack depth	800 mm
Rack width	1785 mm
Rack height	3000 mm
Insert thickness	25 mm
Height adjustment interval	25 mm
Type of installation	Plug-in racking
Colour selection	RAL 5010, 2004
Product name attribute	Depth 800 mm
Type of product	Wide-span racking