


Wide-span add-on rack, Depth 600 mm, Height / Shelf width: 2500/2140mm

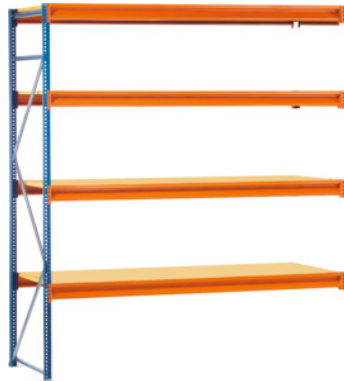

Order data

Order number	990985 2500/2140
GTIN	4004514225405
Item class	960

Description

Version:

Framework galvanised. Optionally galvanised 25 mm steel panels or chipboard. Different types of cross beam depending on the required load per shelf (cross piece height 55 – 85 mm). Quick assembly by simply plugging in the type ZG cross beams. **Shelf loading** maximum 1050 kg, **bay loading** maximum 3500 kg.

Description:

Assembled size:

Nominal length + number of stiles × 57 mm.

Application:

Storage of bulky, awkward, and heavy goods. Deposit and retrieval available from both sides.

Colour:

Stiles similar RAL 5017 Traffic blue, cross beams similar to RAL 2004 Pure orange **powder-coated**.

Note:

- **The free unsupported length (K) must not be more than 1200 mm, but only for a bay load of max. 2600 kg. The permissible bay load must be reduced in recognition of this shelf.**
- **Floor and wall fastenings are not included.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

Technical description

Height	2500 mm
Shelf load capacity	950 kg
Width	2197 mm
Customer assembly	yes
Assembled size add-on rack width	2197 mm
Material of storage level	Chipboard shelf
Storage shelf depth	600 mm
Shelf width	2140 mm
Rack installation	Extension rack
Number of storage levels chipboard shelf	4
Depth	600 mm
Rack depth	600 mm
Rack width	2140 mm
Rack height	2500 mm
Insert thickness	25 mm
Height adjustment interval	25 mm
Type of installation	Plug-in racking
Colour selection	RAL 5010, 2004
Product name attribute	Depth 600 mm
Type of product	Wide-span racking