




## Work platform individual module, Type: B

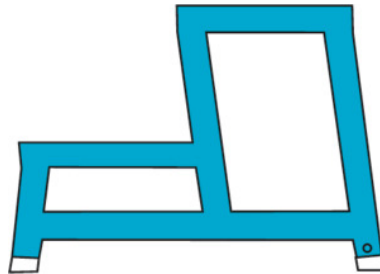

### Order data

Order number	966150 B
GTIN	4003866402601
Item class	96Z

### Description

#### Version:

Extremely robust, torsion-resistant, corrosion-proof, and weatherproof aluminium alloy structure. Steps of serrated aluminium plate 555×250 mm.

Modular structure allows changes and extensions.

Add-on modules available for 4 different heights.

The two-step basic module with up to 3 add-on steps is suitable for mobile use. Add-on modules available from module type B.

#### Standard:

**DIN EN 14183.**

### Technical description

Platform height without railing	0.4 m
Working height	2.4 m
Weight of individual module	4.8 kg
Rung/step width	555 mm
Standard	DIN EN 14183
Type of step	Step

Rung/step depth	250 mm
Module combination	B
Platform depth	0.55 m
Material	Overall light alloy design; steps of ribbed aluminium plate.
Accessibility	single-sided
Number of steps including platform	2
Ladders and platforms load capacity	150 kg
Type of product	Work platform