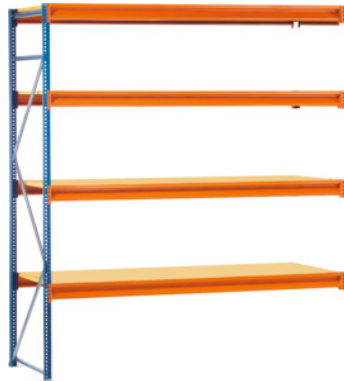


Wide-span add-on rack, Depth 1000 mm, Height / Shelf width: 2500/2500mm**Order data**

| | |
|--------------|------------------|
| Order number | 991005 2500/2500 |
| GTIN | 4004514225474 |
| Item class | 960 |

Description**Version:**

Framework galvanised. Optionally galvanised 25 mm steel panels or chipboard. Different types of cross beam depending on the required load per shelf (cross piece height 55 – 85 mm). Quick assembly by simply plugging in the type ZG cross beams. **Shelf loading** maximum 1050 kg, **bay loading** maximum 3500 kg.

Description:**Assembled size:**

Nominal length + number of stiles × 57 mm.

Application:

Storage of bulky, awkward, and heavy goods. Deposit and retrieval available from both sides.

Colour:

Stiles similar RAL 5017 Traffic blue, cross beams similar to RAL 2004 Pure orange **powder-coated**.

Note:

- **The free unsupported length (K) must not be more than 1200 mm, but only for a bay load of max. 2600 kg. The permissible bay load must be reduced in recognition of this shelf.**
- **Floor and wall fastenings are not included.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

Technical description

| | |
|--|-------------------|
| Shelf width | 2500 mm |
| Shelf load capacity | 1050 kg |
| Assembled size add-on rack width | 2557 mm |
| Material of storage level | Chipboard shelf |
| Number of storage levels chipboard shelf | 4 |
| Customer assembly | yes |
| Storage shelf depth | 1000 mm |
| Height | 2500 mm |
| Rack installation | Extension rack |
| Width | 2557 mm |
| Depth | 1000 mm |
| Rack depth | 1000 mm |
| Rack width | 2500 mm |
| Rack height | 2500 mm |
| Insert thickness | 25 mm |
| Height adjustment interval | 25 mm |
| Type of installation | Plug-in racking |
| Colour selection | RAL 5010, 2004 |
| Product name attribute | Depth 1000 mm |
| Type of product | Wide-span racking |