


## Wide-span add-on rack, Depth 1000 mm, Height / Shelf width: 3000/1785mm

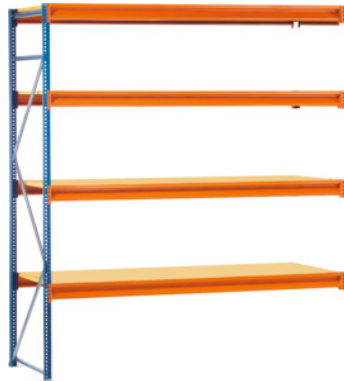

### Order data

Order number	991005 3000/1785
GTIN	4004514225634
Item class	960

### Description

#### Version:

Framework galvanised. Optionally galvanised 25 mm steel panels or chipboard. Different types of cross beam depending on the required load per shelf (cross piece height 55 – 85 mm). Quick assembly by simply plugging in the type ZG cross beams. **Shelf loading** maximum 1050 kg, **bay loading** maximum 3500 kg.

#### Description:

#### Assembled size:

Nominal length + number of stiles × 57 mm.

#### Application:

Storage of bulky, awkward, and heavy goods. Deposit and retrieval available from both sides.

#### Colour:

Stiles similar RAL 5017 Traffic blue, cross beams similar to RAL 2004 Pure orange **powder-coated**.

#### Note:

- **The free unsupported length (K) must not be more than 1200 mm, but only for a bay load of max. 2600 kg. The permissible bay load must be reduced in recognition of this shelf.**
- **Floor and wall fastenings are not included.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

### Technical description

Shelf width	1785 mm
Storage shelf depth	1000 mm
Height	3000 mm
Width	1842 mm
Assembled size add-on rack width	1842 mm
Shelf load capacity	670 kg
Material of storage level	Chipboard shelf
Customer assembly	yes
Rack installation	Extension rack
Number of storage levels chipboard shelf	5
Depth	1000 mm
Rack depth	1000 mm
Rack width	1785 mm
Rack height	3000 mm
Insert thickness	25 mm
Height adjustment interval	25 mm
Type of installation	Plug-in racking
Colour selection	RAL 5010, 2004
Product name attribute	Depth 1000 mm
Type of product	Wide-span racking