


## Wide-span add-on rack, Depth 1000 mm, Height / Shelf width: 3000/2140mm

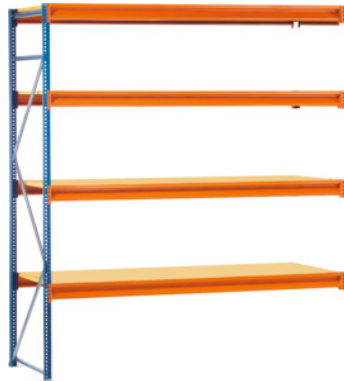

### Order data

Order number	991005 3000/2140
GTIN	4004514225641
Item class	960

### Description

#### Version:

Framework galvanised. Optionally galvanised 25 mm steel panels or chipboard. Different types of cross beam depending on the required load per shelf (cross piece height 55 – 85 mm). Quick assembly by simply plugging in the type ZG cross beams. **Shelf loading** maximum 1050 kg, **bay loading** maximum 3500 kg.

#### Description:

#### Assembled size:

Nominal length + number of stiles × 57 mm.

#### Application:

Storage of bulky, awkward, and heavy goods. Deposit and retrieval available from both sides.

#### Colour:

Stiles similar RAL 5017 Traffic blue, cross beams similar to RAL 2004 Pure orange **powder-coated**.

#### Note:

- **The free unsupported length (K) must not be more than 1200 mm, but only for a bay load of max. 2600 kg. The permissible bay load must be reduced in recognition of this shelf.**
- **Floor and wall fastenings are not included.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

### Technical description

Height	3000 mm
Customer assembly	yes
Material of storage level	Chipboard shelf
Storage shelf depth	1000 mm
Number of storage levels chipboard shelf	5
Shelf load capacity	950 kg
Rack installation	Extension rack
Assembled size add-on rack width	2197 mm
Width	2197 mm
Shelf width	2140 mm
Depth	1000 mm
Rack depth	1000 mm
Rack width	2140 mm
Rack height	3000 mm
Insert thickness	25 mm
Height adjustment interval	25 mm
Type of installation	Plug-in racking
Colour selection	RAL 5010, 2004
Product name attribute	Depth 1000 mm
Type of product	Wide-span racking