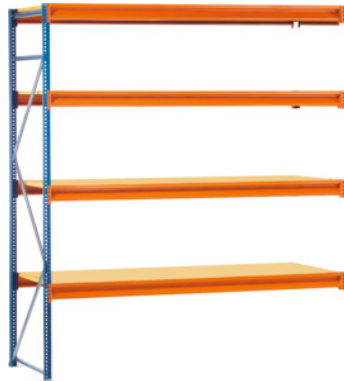


**Wide-span add-on rack, Depth 1000 mm, Height / Shelf width: 2000/2500mm****Order data**

Order number	991005 2000/2500
GTIN	4004514225290
Item class	960

**Description****Version:**

Framework galvanised. Optionally galvanised 25 mm steel panels or chipboard. Different types of cross beam depending on the required load per shelf (cross piece height 55 – 85 mm). Quick assembly by simply plugging in the type ZG cross beams. **Shelf loading** maximum 1050 kg, **bay loading** maximum 3500 kg.

**Description:****Assembled size:**

Nominal length + number of stiles × 57 mm.

**Application:**

Storage of bulky, awkward, and heavy goods. Deposit and retrieval available from both sides.

**Colour:**

Stiles similar RAL 5017 Traffic blue, cross beams similar to RAL 2004 Pure orange **powder-coated**.

**Note:**

- **The free unsupported length (K) must not be more than 1200 mm, but only for a bay load of max. 2600 kg. The permissible bay load must be reduced in recognition of this shelf.**
- **Floor and wall fastenings are not included.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

**Technical description**

Shelf load capacity	1050 kg
Material of storage level	Chipboard shelf
Number of storage levels chipboard shelf	3
Storage shelf depth	1000 mm
Shelf width	2500 mm
Rack installation	Extension rack
Customer assembly	yes
Width	2557 mm
Assembled size add-on rack width	2557 mm
Height	2000 mm
Depth	1000 mm
Rack depth	1000 mm
Rack width	2500 mm
Rack height	2000 mm
Insert thickness	25 mm
Height adjustment interval	25 mm
Type of installation	Plug-in racking
Colour selection	RAL 5010, 2004
Product name attribute	Depth 1000 mm
Type of product	Wide-span racking