


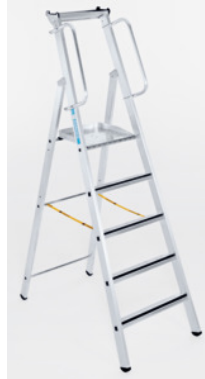

Stepladder with platform, single-sided access, Number of steps including platform: 3



Order data

Order number	966272 3
GTIN	4003866416325
Item class	96Z

Description

Version:

Stepladder with flanged steps 80 mm deep. Large working platform with aluminium chequer plate covering (380×390 mm). Aluminium storage tray. 2 handrails as standard, for safe ascent and descent. Optimum stability due to 2 high-strength perlon belts that prevent splay (from 5 treads).

Standard:

EN 131.

Technical description

Platform depth	390 mm
outer width at bottom	0.59 m
Accessibility	single-sided
Storage tray available	yes
Number of steps including platform	3

Standard	EN 131
Weight	9.5 kg
Rung/step depth	80 mm
Belt to prevent splay	2 high-strength Perlon belts
Platform height without railing	0.77 m
Handrail	2
Platform width	380 mm
Working height approx.	2.8 m
Ladders and platforms load capacity	150 kg
Two hands free principle	yes
Safer Step	yes
Type of product	Platform ladder