


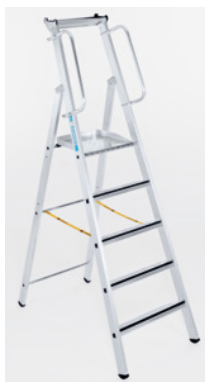

## Stepladder with platform, single-sided access, Number of steps including platform: 4



### Order data

Order number	966272 4
GTIN	4003866416332
Item class	96Z

### Description

#### Version:

Stepladder with flanged steps 80 mm deep. Large working platform with aluminium chequer plate covering (380×390 mm). Aluminium storage tray. 2 handrails as standard, for safe ascent and descent. Optimum stability due to 2 high-strength perlon belts that prevent splay (from 5 treads).

#### Standard:

EN 131.

### Technical description

Rung/step depth	80 mm
Platform width	380 mm
Weight	11 kg
Working height approx.	3 m
Belt to prevent splay	2 high-strength Perlon belts

Platform height without railing	1.03 m
Storage tray available	yes
Handrail	2
Accessibility	single-sided
Standard	EN 131
Platform depth	390 mm
Number of steps including platform	4
outer width at bottom	0.62 m
Ladders and platforms load capacity	150 kg
Two hands free principle	yes
Safer Step	yes
Type of product	Platform ladder