




## Stepladder with platform, single-sided access, Number of steps including platform: 5

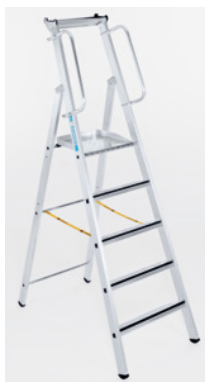

### Order data

Order number	966272 5
GTIN	4003866416349
Item class	96Z

### Description

**Version:**

Stepladder with flanged steps 80 mm deep. Large working platform with aluminium chequer plate covering (380×390 mm). Aluminium storage tray. 2 handrails as standard, for safe ascent and descent. Optimum stability due to 2 high-strength perlon belts that prevent splay (from 5 treads).

**Standard:**

**EN 131.**

### Technical description

Handrail	2
Weight	12 kg
Platform height without railing	1.29 m
Accessibility	single-sided
Platform width	380 mm

Rung/step depth	80 mm
Working height approx.	3.3 m
Standard	EN 131
Platform depth	390 mm
Number of steps including platform	5
Belt to prevent splay	2 high-strength Perlon belts
Storage tray available	yes
outer width at bottom	0.65 m
Ladders and platforms load capacity	150 kg
Two hands free principle	yes
Safer Step	yes
Type of product	Platform ladder