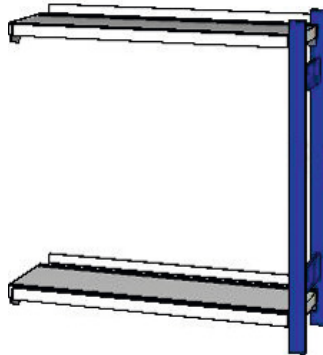


**Garant****Add-on filing rack with 1 column frame, Depth 325 mm, Height: 1000mm****Order data**

Order number	990405 1000
GTIN	4045197517821
Item class	911

**Description****Version:**

Sturdy column frame of rectangular columns (50×25×1.25 mm) with slots at intervals of 40 mm for mounting cross beams / shelves. Column frame with plastic end caps. **Storage shelves** of galvanised sheet metal, **slotted for insertion of dividers**, with bent-up stop rail to prevent items being pushed through.

**Colour:**

Column frame signal blue RAL 5005 **powder-coated**. Pairs of cross beams are **always** anthracite grey RAL 7016.

**Note:**

- **To ensure the stability of the racks, measures to prevent tipping are necessary where the height to depth ratio is greater than 5:1.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

**Technical description**

Depth	325 mm
Number of profile frames	1

Width	975 mm
suitable for number of files	20
Assembled size add-on rack width	975 mm
Shelf width	946 mm
Stop rail	yes
Height	1000 mm
Storage shelf clear width	900 mm
maximum bay load	900 kg
Number of shelves	2
Storage shelf depth	325 mm
Shelf load capacity / maximum distributed shelf load (on metal)	120 kg
Height adjustment interval	40 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Product name attribute	Depth 325 mm
Type of product	File racking

---

## Accessories

Storage shelf, galvanised with pair of cross beams	990430
Dividers set 5 pieces	990450