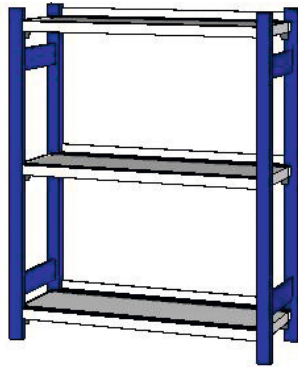


Garant**Basic filing rack with 2 column frames, Depth 325 mm, Height: 1200mm****Order data**

Order number	990400 1200
GTIN	4045197517784
Item class	911

Description**Version:**

Sturdy column frame of rectangular columns (50×25×1.25 mm) with slots at intervals of 40 mm for mounting cross beams / shelves. Column frame with plastic end caps. **Storage shelves** of galvanised sheet metal, **slotted for insertion of dividers**, with bent-up stop rail to prevent items being pushed through.

Colour:

Column frame signal blue RAL 5005 **powder-coated**. Pairs of cross beams are **always** anthracite grey RAL 7016.

Note:

- **To ensure the stability of the racks, measures to prevent tipping are necessary where the height to depth ratio is greater than 5:1.**
- **Supplied for self-assembly, saving freight costs. Delivered unassembled.**

Technical description

Number of shelves	3
suitable for number of files	30

Width	1000 mm
Shelf width	946 mm
maximum bay load	900 kg
Assembled size basic rack width	1000 mm
Height	1200 mm
Storage shelf clear width	900 mm
Depth	325 mm
Number of profile frames	2
Stop rail	yes
Storage shelf depth	325 mm
Shelf load capacity / maximum distributed shelf load (on metal)	120 kg
Height adjustment interval	40 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Product name attribute	Depth 325 mm
Type of product	File racking

Accessories

Dividers set 5 pieces	990450
Storage shelf, galvanised with pair of cross beams	990430