


## PRYOR

Steel type punches individually exchangeable, for set No. 085480, Character height / Characters: 2,5/&mm

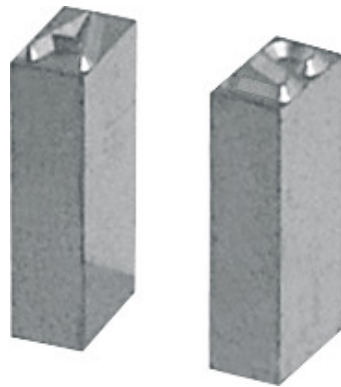

### Order data

|              |               |
|--------------|---------------|
| Order number | 085481 2,5/&  |
| GTIN         | 5022044020856 |
| Item class   | 08W           |

### Description

#### Version:

Size 1.5/\* to size 5/\* = number (0 - 9), letter (A -Z) and special characters (&, /, +, -, full stop, comma).

Size 1.5LEER to size 5LEER – spacer piece.

#### Note:

**The asterisk in the stated size acts as a placeholder for the required characters.**

When ordering please state the size (e.g. 3/\*) to be extended with the desired character, e.g. 3/1, 3/A or 3/& etc.

Width of punch type: 2.4 mm

Punch type depth: 19.05 mm

Height of punch type: 6.35 mm

### Technical description

|                      |          |
|----------------------|----------|
| Character height     | 2.5 mm   |
| Height of punch type | 6.35 mm  |
| Punch type depth     | 19.05 mm |

|                     |            |
|---------------------|------------|
| Width of punch type | 2.4 mm     |
| Character           | AND symbol |
| Type of product     | Hand punch |