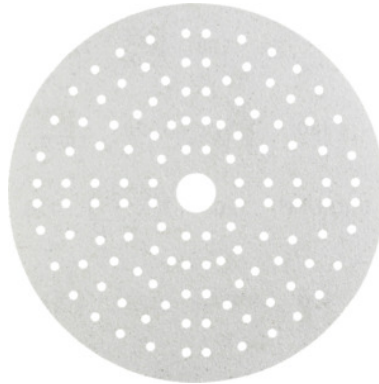


**MIRKA****Velour-backed abrasive disc (CER) Multiple holes, Ø 150 mm, Grit: 40****Order data**

Order number	567557 40
GTIN	6416868234961
Item class	56M

**Description****Version:**

Velour-backed abrasive disc with **paper backing**. Dust-repellent coating prevents premature clogging. The back is covered with hooks and loops.

Velour-backed abrasive disc **MIRKA IRIDIUM®** with a mixture of ceramic grit (CER) and aluminium oxide grit (A), dust-repellent coating, high material removal rate and long service life.

**Application:**

On **orbital sanders** with hook and loop pads e.g.No. 567990 (dust extraction available).

Universal **all-round product** for coarse, intermediate and fine abrasion on all metal and plastic surfaces, paint systems and woods.

Ideal for **soft** and **hard surfaces**.

**Technical description**

Grit	40
Series	IRIDIUM®
Disc Ø	150 mm
Grinding media	Ceramic grit (CER)

Grinding media	Aluminium oxide mineral particles (A)
Grinding medium code	Stainless steel
Grinding medium code	A
Iron, sulphur and chlorine constituents	< 0.1 %
Product name attribute	Ø 150 mm
Dust extraction possible	yes
maximum circumferential speed	40 m/s
Type of product	Velour-backed abrasive disc

### User data

	Suitability	V <sub>c</sub>	ISO code
Alu Mg	Suitable		
Steel < 900 N/mm <sup>2</sup>	Suitable		
Steel < 1400 N/mm <sup>2</sup>	Suitable		
Steel < 55 HRC	Suitable		
Steel < 60 HRC	Suitable		
Steel < 67 HRC	Suitable only under restricted conditions		
INOX	Suitable		
Ti	Suitable only under restricted conditions		
CuZn	Suitable		
Plastic, GRP	Suitable		
Wood	Suitable		
Paint	Suitable		
Uni	Suitable		
dry	Suitable		