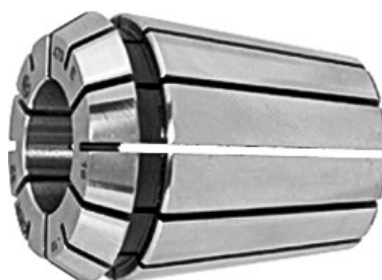


**FAHRION®**  
FAHRENDEN PROTEKTION**ER collet, ER 11, Nominal clamping Ø d: 1 mm****Order data**

|              |               |
|--------------|---------------|
| Order number | 308881 1      |
| GTIN         | 2050001767974 |
| Item class   | 39Y           |

**Description****Version:**

Through hardened and ground.

**Corrosion protection:** Collets fully coated with FAHRION Protect, including the functional faces.

**Advantage:**

The coating increases the service life of the collet and ensures full functionality and precision.

**Note:**

The **collet clamping Ø range is always up to 1 mm less than nominal**, e.g. Ø 10 – 9 mm, **except for Ø 1, 1.5 and 2 (where it is only 0.5 mm).**

**Technical description**

|                      |             |
|----------------------|-------------|
| Nominal clamping Ø d | 1 mm        |
| Adapter              | ER 11       |
| Standard             | ISO 15488-B |
| Concentricity        | ≤ 5 µm      |
| Type                 | 4008 E      |
| External Ø D         | 11.3 mm     |
| Overall length L     | 18 mm       |

Type of product

Collet