


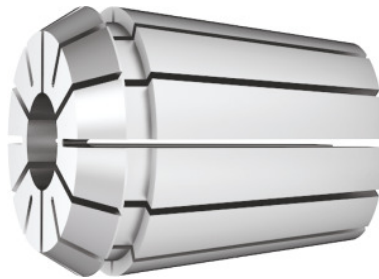

## ER collet, ER 40, Nominal clamping $\varnothing$ d: 22mm



### Order data

Order number	308990 22
GTIN	2050001765383
Item class	39Y

### Description

#### Version:

Through hardened and ground.

**Corrosion protection:** Collets fully coated with FAHRION Protect, including the functional faces.

#### Advantage:

The coating increases the service life of the collet and ensures full functionality and precision.

#### Note:

The **collet clamping  $\varnothing$  range** is **always up to 1 mm less than nominal**, e.g.  $\varnothing$  10 – 9 mm, **except for  $\varnothing$  1, 1.5 and 2 (where it is only 0.5 mm)**.

### Technical description

Nominal clamping $\varnothing$ d	22 mm
Adapter	ER 40
Standard	ISO 15488-B
Concentricity	$\leq 5 \mu\text{m}$
Type	472 E
External $\varnothing$ D	41 mm
Overall length L	46 mm

Type of product

Collet