


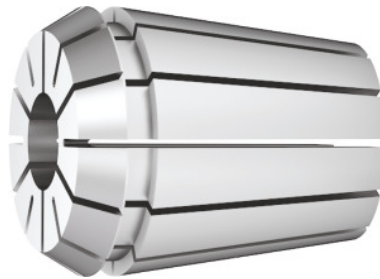

ER collet, ER 40, Nominal clamping \varnothing d: 11 mm



Order data

| | |
|--------------|---------------|
| Order number | 308990 11 |
| GTIN | 2050001765352 |
| Item class | 39Y |

Description

Version:

Through hardened and ground.

Corrosion protection: Collets fully coated with FAHRION Protect, including the functional faces.

Advantage:

The coating increases the service life of the collet and ensures full functionality and precision.

Note:

The **collet clamping \varnothing range** is **always up to 1 mm less than nominal**, e.g. \varnothing 10 – 9 mm, **except for \varnothing 1, 1.5 and 2 (where it is only 0.5 mm)**.

Technical description

| | |
|----------------------------------|----------------------|
| Nominal clamping \varnothing d | 11 mm |
| Adapter | ER 40 |
| Standard | ISO 15488-B |
| Concentricity | $\leq 5 \mu\text{m}$ |
| Type | 472 E |
| External \varnothing D | 41 mm |
| Overall length L | 46 mm |

Type of product

Collet