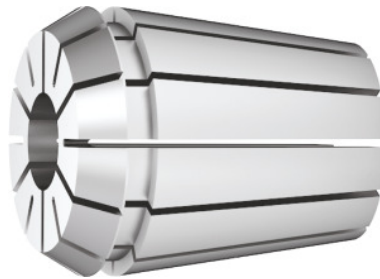


**FAHRION®**  
FAHRENDEN PROTEKTION**ER collet, ER 40, Nominal clamping Ø d: 19mm****Order data**

Order number	308990 19
GTIN	2050001766885
Item class	39Y

**Description****Version:**

Through hardened and ground.

**Corrosion protection:** Collets fully coated with FAHRION Protect, including the functional faces.

**Advantage:**

The coating increases the service life of the collet and ensures full functionality and precision.

**Note:**

The **collet clamping Ø range** is **always up to 1 mm less than nominal**, e.g. Ø 10 – 9 mm, **except for Ø 1, 1.5 and 2 (where it is only 0.5 mm)**.

**Technical description**

Nominal clamping Ø d	19 mm
Adapter	ER 40
Standard	ISO 15488-B
Concentricity	≤ 5 µm
Type	472 E
External Ø D	41 mm
Overall length L	46 mm

Type of product

Collet