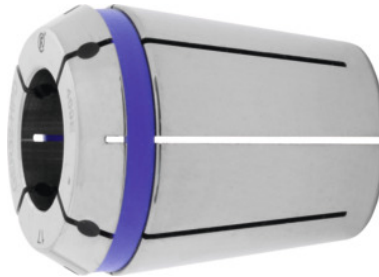


**FAHRION®**  
FAHRENDEN PROZESSION
**ER collet HP with seal, ER 32, Nominal clamping Ø d: 10mm**

**Order data**

Order number	309377 10
GTIN	2050001767608
Item class	33F

**Description**
**Version:**

**System concentricity** and repetition accuracy **3 µm** (3xD, maximum = 50 mm), in conjunction with FAHRION CENTRO P chucks.

**Corrosion protection:** Collets fully coated with FAHRION Protect, including the functional faces.

**Advantage:**

The coating increases the service life of the collet and ensures full functionality and precision.

**Suitable for:**

Precision ER collet chuck CENTRO P.

**Note:**

- **Optimum concentricity only when used in CENTRO P chucks.**
- **Clamping range h10 (nominal size only).**

With **seal** for through-coolant feed (for use up to 60 bar). **Similar to** ISO 15488-A.

**Technical description**

Nominal clamping Ø d	10 mm
Adapter	ER 32
Standard	ISO 15488-A
Concentricity	≤ 2 µm
Type	469 E

External $\varnothing$ D	32.7 mm
Overall length L	40 mm
Type of product	Collet