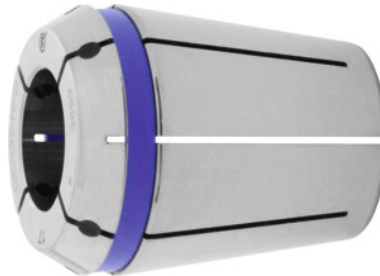


FAHRION®
PRAZISION
ER collet HP with seal, ER 40, Nominal clamping Ø d: 10 mm

Order data

Order number	309380 10
GTIN	2050001767516
Item class	33F

Description
Version:

System concentricity and repetition accuracy **3 µm** (3×D, maximum = 50 mm), in conjunction with FAHRION CENTRO P chucks.

Corrosion protection: Collets fully coated with FAHRION Protect, including the functional faces.

Advantage:

The coating increases the service life of the collet and ensures full functionality and precision.

Suitable for :

Precision ER collet chuck CENTRO P.

Note:

- **Optimum concentricity only when used in CENTRO P chucks.**
- **Clamping range h10 (nominal size only).**

With **seal** for through-coolant feed (for use up to 100 bar). **Similar to** ISO 15488-A.

Concentricity: ≤ 2 µm

Overall length L: 46 mm

Technical description

Nominal clamping Ø d	10 mm
Adapter	ER 40
Standard	ISO 15488-A

Concentricity	≤ 2 μm
Type	471 E
External Ø D	40.7 mm
Overall length L	46 mm
Type of product	Clamping head