


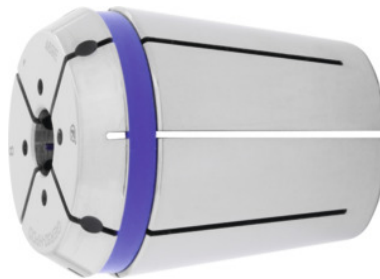

ER collet HP with seal and spray nozzles, ER 16, Nominal clamping \varnothing d: 4mm



Order data

Order number	309372 4
GTIN	2050001768599
Item class	33F

Description

Version:

System concentricity and repetition accuracy **3 μ m** ($3 \times D$, maximum = 50 mm), in conjunction with FAHRION CENTRO P chucks.

Corrosion protection: Collets fully coated with FAHRION Protect, including the functional faces.

Advantage:

The coating increases the service life of the collet and ensures full functionality and precision.

Suitable for:

Precision ER collet chuck CENTRO P.

Note:

- **Optimum concentricity only when used in CENTRO P chucks.**
- **Clamping range h10 (nominal size only).**

With **seal** for through-coolant feed (for use up to 60 bar) and **spray nozzles**. **Similar to ISO 15488-A.**

Technical description

Nominal clamping \varnothing d	4 mm
Adapter	ER 16
Standard	ISO 15488-A
Concentricity	$\leq 2 \mu$ m

Type	425 E
External Ø D	16.7 mm
Overall length L	27.5 mm
Type of product	Collet