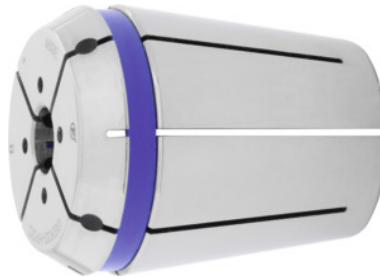


FAHRION®
FAHRENDEN PRESSION
ER collet HP with seal and spray nozzles, ER 16, Nominal clamping Ø d: 6mm

Order data

Order number	309372 6
GTIN	2050001766816
Item class	33F

Description
Version:

System concentricity and repetition accuracy **3 µm** (3×D, maximum = 50 mm), in conjunction with FAHRION CENTRO P chucks.

Corrosion protection: Collets fully coated with FAHRION Protect, including the functional faces.

Advantage:

The coating increases the service life of the collet and ensures full functionality and precision.

Suitable for:

Precision ER collet chuck CENTRO P.

Note:

- **Optimum concentricity only when used in CENTRO P chucks.**
- **Clamping range h10 (nominal size only).**

With **seal** for through-coolant feed (for use up to 60 bar) and **spray nozzles**. **Similar to ISO 15488-A.**

Technical description

Nominal clamping Ø d	6 mm
Adapter	ER 16
Standard	ISO 15488-A
Concentricity	≤ 2 µm

Type	425 E
External Ø D	16.7 mm
Overall length L	27.5 mm
Type of product	Collet