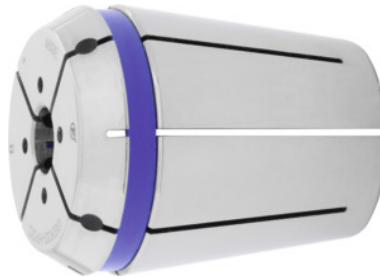


FAHRION®
FAHRENDEN PRESSION
ER collet HP with seal and spray nozzles, ER 32, Nominal clamping Ø d: 20mm

Order data

| | |
|--------------|---------------|
| Order number | 309378 20 |
| GTIN | 2050001766830 |
| Item class | 33F |

Description
Version:

System concentricity and repetition accuracy **3 µm** (3×D, maximum = 50 mm), in conjunction with FAHRION CENTRO P chucks.

Corrosion protection: Collets fully coated with FAHRION Protect, including the functional faces.

Advantage:

The coating increases the service life of the collet and ensures full functionality and precision.

Suitable for:

Precision ER collet chuck CENTRO P.

Note:

- **Optimum concentricity only when used in CENTRO P chucks.**
- **Clamping range h10 (nominal size only).**

With **seal** for through-coolant feed (for use up to 60 bar) and **spray nozzles**. **Similar to ISO 15488-A.**

Technical description

| | |
|----------------------|-------------|
| Nominal clamping Ø d | 20 mm |
| Adapter | ER 32 |
| Standard | ISO 15488-A |
| Concentricity | ≤ 2 µm |

| | |
|------------------|---------|
| Type | 469 E |
| External Ø D | 32.7 mm |
| Overall length L | 40 mm |
| Type of product | Collet |