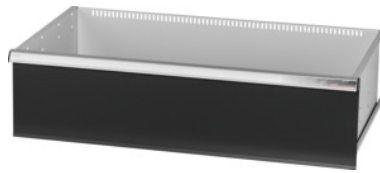


Garant GRIDLINE

Drawer, 200 kg, 36×20G, Drawer front height: 250mm**Order data**

Order number	930745 250
GTIN	4062406064242
Item class	9GK

Description**Version:**

100% full extension drawers with differential runners. Aluminium handle with labelling strips that can be exchanged and rewritten.

Slots at 25 mm intervals to take slotted dividers (from drawer front height 75 mm).

Load capacity 200 kg.

Suitable for:

Tool cabinet casing 40×24G No. 930735.

Supplied with:

Drawers each complete with 1 pair drawer runner rails.

Colour:

Drawer body RAL 7035 light grey, drawer fronts RAL 7016 anthracite, **powder-coated. Drawer body not configurable, always RAL 7035 light grey.**

Technical description

Drawer/pull-out shelf load capacity	200 kg
Drawer usable area in G	36×20
Weight	22 kg
Usable height	225 mm
Front height	250 mm
Usable width in G	36
Usable depth in G	20

Application range	Tool cabinet
Usable depth	500 mm
Usable width	900 mm
with individual drawer release system	no
Material thickness	1.2 mm
Drawer runner extension (partial/full extension)	100 %
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Drawer usable width × usable depth in G	36×20G
Type of product	Drawer

Accessories

Ribbed rubber mat for drawers Dimension in G 36X20	951910 36X20
Pack of PVC covers for handles 10 pieces Drawer usable width in G 36	951032 36
Handle end caps 20 pieces Type 10	951025 10
Labelling strip set 10 pieces Drawer usable width in G 36	951030 36