


Garant GRIDLINE

Drawers for swing-door large-capacity cabinets and heavy-duty cabinets Width 30G, 26×24G, Drawer front height: 150mm

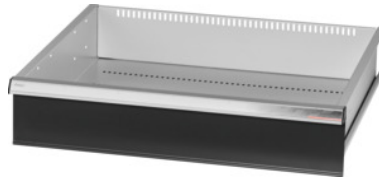

Order data

| | |
|--------------|---------------|
| Order number | 942570 150 |
| GTIN | 4062406067762 |
| Item class | 9GI |

Description

Version:

Drawers for incorporating in GridLine **swing-door** large-capacity cabinets and heavy-duty cabinets.

Aluminium handles with labelling strips that can be exchanged and rewritten. New type of drawer concept for optimum equipment with dividing material.

Suitable for:

Cabinets No. 941001 – 941033; No. 942301 – 942323; No. 942701 – 942723, No. 942802 – 942824.

Colour:

Drawer body RAL 7035 light grey, drawer fronts RAL 7016 anthracite, **powder-coated. Drawer body not configurable, always RAL 7035 light grey.**

Note:

Size 30 and size 40 are suitable for cabinets of width 60G and 80G, since these have 2 compartments.

Drawers not suitable for sliding door cabinets.

Technical description

| | |
|-------------------|--------|
| Weight | 9 kg |
| Usable height | 125 mm |
| Usable width in G | 26 |
| Usable depth in G | 24 |

| | |
|--|--|
| Usable depth | 600 mm |
| Usable width | 650 mm |
| Material thickness | 0.9 mm |
| Drawer/pull-out shelf load capacity | 75 kg |
| Drawer runner extension (partial/full extension) | 100 % |
| Colour selection | RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003 |
| Drawer usable width × usable depth in G | 26×24G |
| Type of product | Drawer |

Accessories

| | |
|---|--------------|
| Non-slip mats set for drawers,5 pieces Dimension in G 26X24 | 951885 26X24 |
| Mat for drawers Dimension in G 26X24 | 951830 26X24 |
| Ribbed rubber mat for drawers Dimension in G 26X24 | 951910 26X24 |