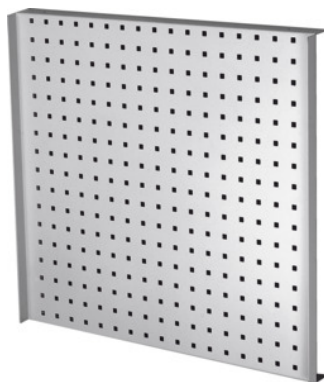


Garant GRIDLINE

**Perforated panel single-sided, suitable for upright cabinet height: 2000 mm****Order data**

Order number	942015 2000
GTIN	4062406068523
Item class	9GI

**Description****Version:**

Perforated panel with  $\square$  9x9 mm holes at 37 mm pitch. For mounting hooks, brackets and perforated panel accessories on one side, these can be found in Group 95. Usable dimension for hooks when fitted in No. 942002 250 mm / 40 mm, optionally 135 mm / 135 mm. When fitted in No. 942004, 75 mm / 40 mm, cannot be fitted centrally.

**Suitable for :**

2-part – fills one pull-out frame of cabinet No. 942002, 942004 size 2000.

**Colour:**

RAL 7035 light grey **powder coated.**

Colour selection: RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003

Height: 1671 mm

Width: 627 mm

Weight: 8 kg

**Technical description**

Weight	8 kg
Height	1671 mm

Width	627 mm
suitable for upright cabinet height	2000 mm
Material thickness	1.2 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Perforated panel for upright cabinet