


Garant GRIDLINE

Perforated panel single-sided, suitable for upright cabinet height: 1000 mm

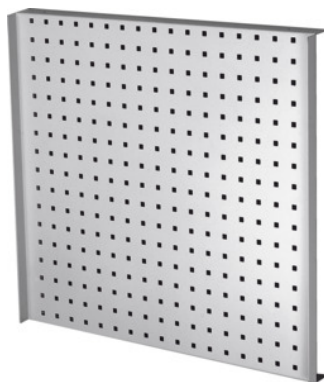

Order data

Order number	942015 1000
GTIN	4062406068516
Item class	9GI

Description

Version:

Perforated panel with \square 9x9 mm holes at 37 mm pitch. For mounting hooks, brackets and perforated panel accessories on one side, these can be found in Group 95. Usable dimension for hooks when fitted in No. 942002 250 mm / 40 mm, optionally 135 mm / 135 mm. When fitted in No. 942004, 75 mm / 40 mm, cannot be fitted centrally.

Suitable for :

Fills one pull-out frame of cabinet No. 958610 completely.

Colour:

RAL 7035 light grey **powder coated**.

Colour selection: RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003

Height: 667.5 mm

Width: 627 mm

Weight: 6 kg

Technical description

suitable for upright cabinet height	1000 mm
Width	627 mm

Height	667.5 mm
Weight	6 kg
Material thickness	1.2 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Perforated panel for upright cabinet