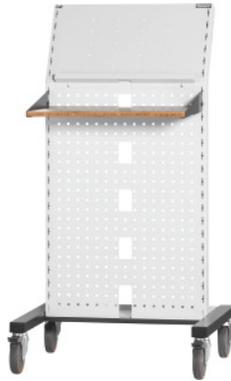


Garant**Computer desk, Type: M****Order data**

Order number	948040 M
GTIN	4062406194482
Item class	91C

Description**Version:**

Suitable for a PC and for a laptop. Screen mounting for PC variant based on VESA mounting, can be attached at the left, right or middle. With a shelf at the rear (internal size WxD: 545x220 mm) and with an attachable shelf (internal size WxD: 570x300 mm). Structure with mobility unit 4 castors, of which 2 with parking brakes Ø 125 mm.

Colour:

RAL 7035 light grey, base frame **always** RAL 7016 anthracite, **powder-coated**.

Recommendation:

For mounting files, hook systems and shelves, no tools required.

Technical description

Footprint depth	550 mm
Footprint width	750 mm
Weight	17 kg
Height	1400 mm

Material thickness	0.9 mm
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Computer desk

Accessories

Shelf for computer desk Type 1	948045 1
--------------------------------	----------