


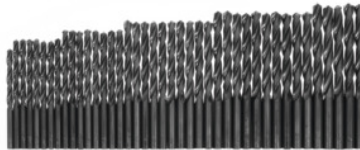

Jobber drill set HSS No. 114000 as refill set, uncoated, Type: 6-10



Order data

| | |
|--------------|---------------|
| Order number | 115020 6-10 |
| GTIN | 4045197024107 |
| Item class | 12B |

Description

Version:

Composed of jobber drills DIN 338.
 Through-coolant: no
 Shank: Plain shank
 Number of cutting edges Z: 2
 Drill range: 6 - 10 mm
 Number of drills: 41
 Incremental steps of drills: 0.1 mm

Technical description

| | |
|---------------------------------|-------------|
| Drill range | 6 - 10 mm |
| Incremental steps of drills | 0.1 mm |
| Number of drills | 41 |
| Shank | Plain shank |
| Number of cutting edges Z | 2 |
| Coating | uncoated |
| Tool material | HSS |
| Type | N |
| Tolerance nominal \varnothing | h8 |

| | |
|-----------------|--------------|
| Point angle | 118 ° |
| Through-coolant | no |
| with case | no |
| Colour ring | without |
| Type of product | Jobber drill |

Accessories

| | |
|---|------------|
| HSS jobber drill roll forged N Ø DC h8 7,9 mm | 114000 7,9 |
| HSS jobber drill roll forged N Ø DC h8 9,1 mm | 114000 9,1 |
| HSS jobber drill roll forged N Ø DC h8 6,5 mm | 114000 6,5 |
| HSS jobber drill roll forged N Ø DC h8 9 mm | 114000 9 |
| HSS jobber drill roll forged N Ø DC h8 8,7 mm | 114000 8,7 |
| HSS jobber drill roll forged N Ø DC h8 7 mm | 114000 7 |
| HSS jobber drill roll forged N Ø DC h8 9,2 mm | 114000 9,2 |
| HSS jobber drill roll forged N Ø DC h8 6,6 mm | 114000 6,6 |
| HSS jobber drill roll forged N Ø DC h8 9,7 mm | 114000 9,7 |
| HSS jobber drill roll forged N Ø DC h8 9,3 mm | 114000 9,3 |
| HSS jobber drill roll forged N Ø DC h8 9,8 mm | 114000 9,8 |
| HSS jobber drill roll forged N Ø DC h8 9,6 mm | 114000 9,6 |
| HSS jobber drill roll forged N Ø DC h8 7,4 mm | 114000 7,4 |
| HSS jobber drill roll forged N Ø DC h8 6,3 mm | 114000 6,3 |
| HSS jobber drill roll forged N Ø DC h8 7,2 mm | 114000 7,2 |
| HSS jobber drill roll forged N Ø DC h8 6,2 mm | 114000 6,2 |
| HSS jobber drill roll forged N Ø DC h8 10 mm | 114000 10 |
| HSS jobber drill roll forged N Ø DC h8 9,4 mm | 114000 9,4 |
| HSS jobber drill roll forged N Ø DC h8 6 mm | 114000 6 |
| HSS jobber drill roll forged N Ø DC h8 7,3 mm | 114000 7,3 |
| HSS jobber drill roll forged N Ø DC h8 8,8 mm | 114000 8,8 |

| | |
|---|------------|
| HSS jobber drill roll forged N Ø DC h8 8 mm | 114000 8 |
| HSS jobber drill roll forged N Ø DC h8 7,6 mm | 114000 7,6 |
| HSS jobber drill roll forged N Ø DC h8 8,4 mm | 114000 8,4 |
| HSS jobber drill roll forged N Ø DC h8 9,9 mm | 114000 9,9 |
| HSS jobber drill roll forged N Ø DC h8 7,5 mm | 114000 7,5 |
| HSS jobber drill roll forged N Ø DC h8 8,9 mm | 114000 8,9 |
| HSS jobber drill roll forged N Ø DC h8 6,9 mm | 114000 6,9 |
| HSS jobber drill roll forged N Ø DC h8 6,4 mm | 114000 6,4 |
| HSS jobber drill roll forged N Ø DC h8 9,5 mm | 114000 9,5 |
| HSS jobber drill roll forged N Ø DC h8 8,6 mm | 114000 8,6 |
| HSS jobber drill roll forged N Ø DC h8 7,1 mm | 114000 7,1 |
| HSS jobber drill roll forged N Ø DC h8 8,1 mm | 114000 8,1 |
| HSS jobber drill roll forged N Ø DC h8 8,2 mm | 114000 8,2 |
| HSS jobber drill roll forged N Ø DC h8 8,3 mm | 114000 8,3 |
| HSS jobber drill roll forged N Ø DC h8 7,8 mm | 114000 7,8 |
| HSS jobber drill roll forged N Ø DC h8 6,7 mm | 114000 6,7 |
| HSS jobber drill roll forged N Ø DC h8 8,5 mm | 114000 8,5 |
| HSS jobber drill roll forged N Ø DC h8 7,7 mm | 114000 7,7 |
| HSS jobber drill roll forged N Ø DC h8 6,8 mm | 114000 6,8 |
| HSS jobber drill roll forged N Ø DC h8 6,1 mm | 114000 6,1 |