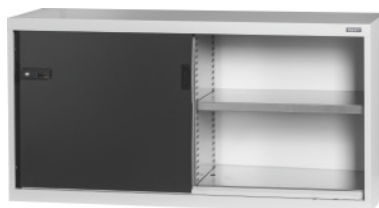


Garant GRIDLINE

Base cabinet with Plain sheet metal sliding doors, Height: 900mm**Order data**

Order number	940165 900
GTIN	4062406069711
Item class	9GI

Description**Version:**

Equipped cabinet in 60×20G. Mountings for shelves at 25 mm intervals. Sliding doors reinforced on the inside and can be locked by 2-component Haptoprene® handle using a cylinder lock. Locks the sliding doors in the end positions (open/closed). **Levelling base** for base cabinets, with 8 individually adjustable feet to compensate for unevenness in the floor. In the base cabinet the handle is mounted in the upper part of the door; in the top-mounted cabinet it is in the lower part of the door.

Supplied with:

Cabinet with storage shelves.

Colour:

Body RAL 7035 light grey, doors RAL 7016 anthracite **powder-coated**.

Note:

For storage shelves and accessories for GridLine cabinets see No. 940501 – 940710 and Group 95. According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

Technical description

Handle positioning	top
Cabinet fronts	Plain sheet metal sliding door
Weight	82 kg
ComfortClose	no

Usable height	763 mm
Number of shelves	2
Height	900 mm
Width in G	60
Depth	500 mm
Shelf load capacity / maximum distributed shelf load (on metal)	100 kg
Electronic locking system can be retrofitted	yes
Depth in G	20
Width	1500 mm
Material thickness	0.9 mm
Cabinet housing internal load capacity	1000 kg
Height adjustment interval	25 mm
Cylinder lock	modular barrel
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of cabinet	Base cabinet
Type of product	Cabinet with shelves

Accessories

Extended lighting set for GridLine cabinets with Sliding doors, width 60G for cabinet height 900 mm	940514 900
Cover made of laminated wood Dimension in G 60X20	951985 60X20
Drawer for sliding door cabinets, Width 30G Drawer front height 100 mm	940651 100
Storage shelf 200 kg for cabinet / compartment width in G 30	940590 30
Drawer for sliding door cabinets, Width 30G Drawer front height 200 mm	940651 200
	940651 150

Drawer for sliding door cabinets,Width 30G Drawer front height 150 mm

Shelf clip set for GridLine cabinets20 pieces Type F

940559 F

Base with removable fascia, depth 20G,Height 150 mm
Cabinet casing in G 60

958146 60

Drawer for sliding door cabinets,Width 30G Drawer front height 75 mm

940651 75

Cover made of bamboo Dimension in G 60X20

951980 60X20

Drawer for sliding door cabinets,Width 30G Drawer front height 125 mm

940651 125

Lock plate for GridLine Type GP21

914227 GP21

Storage shelf for cabinet / compartment width in G 30

940550 30

Drawer for sliding door cabinets,Width 30G Drawer front height 300 mm

940651 300

Storage shelf slotted for cabinet / compartment width in G 30

940552 30

Inclined shelf for cabinet / compartment width in G 30

940560 30